

Modular Cords

GigaFlex PS6+ Modular Cords and GigaFlex PS6+ Bonded Modular Cords Enhanced Category 6

AX350061 GigaFlex PS6+ Modular Cord



GigaFlex PS6+ Modular Cord

The **GigaFlex PS6+ Modular Cords** are 4-pair 23 AWG UTP modular cords designed for use with the Belden IBDN Systems 2400 and 4800LX, providing channel bandwidths of 250 MHz and 300 MHz, respectively. The GigaFlex PS6+ Modular Cords have been designed to provide a mated-connection performance that exceeds the Category 6 requirements.

The GigaFlex PS6+ Modular Cord's patented design, with a very small footprint, makes them fully compatible with any of the highest density hubs with RJ45 jack connections.

Description	Belden Part Number					
	Blue	White	Gray	Green	Red	Yellow

Modular Cords

GigaFlex PS6+ Modular Cord, CMR 4-pair, 23 AWG solid, T568A/B-T568A/B						
0.6 m (2 ft.)	AX350037	AX350043	AX350049	AX350055	AX350061	AX350067
1.2 m (4 ft.)	AX350038	AX350044	AX350050	AX350056	AX350062	AX350068
2.1 m (7 ft.)	AX350039	AX350045	AX350051	AX350057	AX350063	AX350069
3.0 m (10 ft.)	AX350040	AX350046	AX350052	AX350058	AX350064	AX350070
4.6 m (15 ft.)	AX350041	AX350047	AX350053	AX350059	AX350065	AX350071
7.6 m (25 ft.)	AX350042	AX350048	AX350054	AX350060	AX350066	AX350072
4-pair, 23 AWG solid, T568A/B-open						
4.6 m (15 ft.)	AX350160					
7.6 m (25 ft.)	AX350161					
10.6 m (35 ft.)	AX350162					
15.0 m (50 ft.)	AX350163					

These products are in the process of being assessed for RoHS compliance. Please check our Web Site for the most current RoHS status.

AX380014 GigaFlex PS6+ Bonded Modular Cord



GigaFlex PS6+ Bonded Modular Cords

The **GigaFlex PS6+ Bonded Modular Cords** are 4-pair 24 AWG Bonded-Pair UTP modular cords designed for use with the Belden IBDN Systems 2400 and 4800LX, providing channel bandwidths of 250 MHz and 300 MHz, respectively. The GigaFlex PS6+ Bonded Modular Cords have been designed to provide a mated-connection performance that exceeds the Category 6 requirements.

The GigaFlex PS6+ Bonded Modular Cord's patented design, with a very small footprint, makes them fully compatible with the highest density hubs, with any RJ45 jack connections. The special cord design offers increased stability in crosstalk and impedance performance to support the many moves, adds and changes performed in the lifetime of the system.

Description	Belden Part Number			
	Blue	Gray	White	Yellow

Modular Cords

GigaFlex PS6+ Bonded Mod. Cord, CMR, 4-pr, Bonded 24 AWG solid, T568A/B-T568A/B				
1.2 m (4 ft.)	AX380014	AX380026	AX380050	AX380056
2.1 m (7 ft.)	AX380015	AX380027	AX380051	AX380057
3.0 m (10 ft.)	AX380016	AX380028	AX380052	AX380058
4.6 m (15 ft.)	AX380017	AX380029	AX380053	AX380059
7.6 m (25 ft.)	AX380018	AX380030	AX380054	AX380060

These products are in the process of being assessed for RoHS compliance. Please check our Web Site for the most current RoHS status.

Modular Cords

GigaFlex PS5E Modular Cords and GigaFlex PS5E VoIP Cords Category 5E

AX350013 GigaFlex PS5E Modular Cord



GigaFlex PS5E Modular Cord

The **GigaFlex PS5E Modular Cords** are 4-pair 24 AWG UTP modular cords that are designed for use with the Belden IBDN Plus Cabling System and the Belden IBDN System 1200 providing channel bandwidths of 100 MHz and 160 MHz, respectively.

The GigaFlex PS5E Modular Cord's patented design features a very small footprint, making them fully compatible with the highest density hubs which use RJ45 jack connections. The GigaFlex PS5E Modular Cords have been designed to provide a mated-connection performance that exceeds the Category 5e standard.

Description	Belden Part Number					
	Blue	White	Gray	Green	Red	Yellow

Modular Cords

GigaFlex PS5E Mod. Cord, CMR 4-pr, 24 AWG stranded, T568A/B-T568A/B						
0.6 m (2 ft.)	AX350001	AX350007	AX350013	AX350019	AX350025	AX350031
1.2 m (4 ft.)	AX350002	AX350008	AX350014	AX350020	AX350026	AX350032
2.1 m (7 ft.)	AX350003	AX350009	AX350015	AX350021	AX350027	AX350033
3.0 m (10 ft.)	AX350004	AX350010	AX350016	AX350022	AX350028	AX350034
4.6 m (15 ft.)	AX350005	AX350011	AX350017	AX350023	AX350029	AX350035
7.6 m (25 ft.)	AX350006	AX350012	AX350018	AX350024	AX350030	AX350036

AX330015 GigaFlex PS5E VoIP Modular Cord



VoIP Modular Cord features very short body RJ 45 phone connector on other end

GigaFlex PS5E VoIP Modular Cords

The **GigaFlex PS5E VoIP Modular Cords** are 4-pair 24 AWG UTP modular cords that are designed for use with the Belden IBDN Plus Cabling System and the Belden IBDN System 1200 providing channel bandwidths of 100 MHz and 160 MHz, respectively. The GigaFlex PS5E VoIP Modular Cord is designed for use with VoIP phones that can not accommodate standard booted patch cords which would make the phone unstable or difficult to wall mount. The GigaFlex PS5E VoIP Modular Cord is designed with a regular booted RJ 45 plug on one end (at the wall) and a bootless very short body RJ 45 plug on the other end (at the phone). The GigaFlex PS5E VoIP Modular Cords meet all the enhanced Category 5 modular cord requirements as per the Category 5e standard, and are completely backward compatible with Category 5 jacks. The GigaFlex PS5E VoIP Modular Cords have been designed to provide a mated-connection performance that exceeds the Category 5e standard. The GigaFlex PS5E VoIP Modular Cord product line encompass CMR-rated cords.

Description	Belden Part Number					
	Blue	White	Gray	Green	Red	Yellow

Modular Cords


GigaFlex PS5E VoIP Mod.Cord, CMR, 4-pair, 24 AWG stranded,T568A/B-T568A/B						
0.6 m (2 ft.)	AX330013	AX330049	AX330025	AX330019	AX330043	AX330055
1.2 m (4 ft.)	AX330014	AX330050	AX330026	AX330020	AX330044	AX330056
2.1 m (7 ft.)	AX330015	AX330051	AX330027	AX330021	AX330045	AX330057
3.0 m (10 ft.)	AX330016	AX330052	AX330028	AX330022	AX330046	AX330058
4.6 m (15 ft.)	AX330017	AX330053	AX330029	AX330023	AX330047	AX330059
7.6 m (25 ft.)	AX330018	AX330054	AX330030	AX330024	AX330048	AX330060

These products are in the process of being assessed for RoHS compliance. Please check our Web Site for the most current RoHS status.

Modular Cords

Category 5e Modular Cords

Category 5e Modular Cord

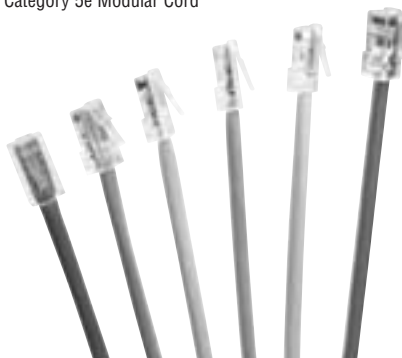

Category 5e Modular Cord

Category 5e Modular Cords are made of plenum and riser rated 24 AWG patch cable.

Description	Belden Part Number					
	Blue	Green	Red	White	Yellow	Gray

Modular Cords

Cat. 5e Modular Cord, CMR, 4-pair, 24 AWG stranded, T568A/B-T568A/B

0.6 m (2 ft.)	23518027	23528027	23538027	23548027	23568027	23598027
1.2 m (4 ft.)	23518047	23528047	23538047	23548047	23568047	23598047
2.1 m (7 ft.)	23518077	23528077	23538077	23548077	23568077	23598077
3.0 m (10 ft.)	23518107	23528107	23538107	23548107	23568107	23598107
4.6 m (15 ft.)	23518157	23528157	23538157	23548157	23568157	23598157
7.6 m (25 ft.)	23518257	23528257	23538257	23548257	23568257	23598257

Cat. 5e X-Over Cord, 4-pair, 24 AWG stranded, T568A-T568B X-Over

2.1 m (7 ft.)	23598074
4.6 m (15 ft.)	23598154
7.6 m (25 ft.)	23598254

Description	Belden Part Number	
	CMR	CMP

Modular Cords

Cat. 5e Modular Cord, Gray, 4-pair, 24 AWG solid, T568A/B-T568A/B

2.1 m (7 ft.)	23498077	23338077
3.0 m (10 ft.)	23498107	23398107
7.6 m (25 ft.)	23498257	23398257
15.0 m (50 ft.)	23498507	23398507
20.1 m (66 ft.)	23498667	23398667

Cat. 5e Pigtails, Gray, 4-pair, 24 AWG solid, T568A/B-open

3.0 m (10 ft.)	23498105	—
4.6 m (15 ft.)	23498155	—
7.6 m (25 ft.)	23498255	23398255
10.6 m (35 ft.)	23498355	23398355
15.0 m (50 ft.)	23498505	23398505

These products are in the process of being assessed for RoHS compliance. Please check our Web Site for the most current RoHS status.