
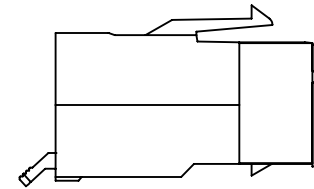
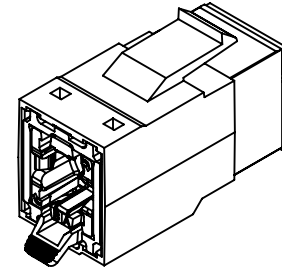
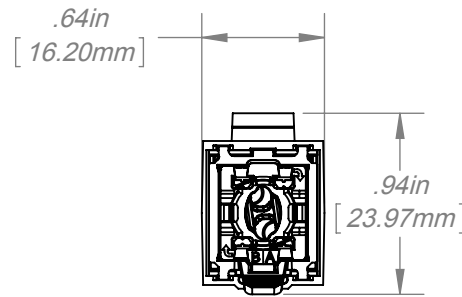


RVAMJKUYL-S1 (Yellow)	REVConn 10GX Jack Yellow UTP T568 A/B Single Pack
RVAMJKUYL-B24 (Yellow)	REVConn 10GX Jack Yellow UTP T568 A/B Bulk Pack
RVAMJKUTY-S1 (Yellow TIA)	REVConn 10GX Jack Yellow TIA UTP T568 A/B Single Pack
RVAMJKUTY-B24 (Yellow TIA)	REVConn 10GX Jack Yellow TIA UTP T568 A/B Bulk Pack
RVAMJKUTR-S1 (Red TIA)	REVConn 10GX Jack Red TIA UTP T568 A/B Single Pack
RVAMJKUTR-B24 (Red TIA)	REVConn 10GX Jack Red TIA UTP T568 A/B Bulk Pack
RVAMJKUTP-S1 (Purple TIA)	REVConn 10GX Jack Purple TIA UTP T568 A/B Single Pack
RVAMJKUTP-B24 (Purple TIA)	REVConn 10GX Jack Purple TIA UTP T568 A/B Bulk Pack
RVAMJKUTO-S1 (Orange TIA)	REVConn 10GX Jack Orange TIA UTP T568 A/B Single Pack
RVAMJKUTO-B24 (Orange TIA)	REVConn 10GX Jack Orange TIA UTP T568 A/B Bulk Pack
RVAMJKUTN-S1 (Brown TIA)	REVConn 10GX Jack Brown TIA UTP T568 A/B Single Pack
RVAMJKUTN-B24 (Brown TIA)	REVConn 10GX Jack Brown TIA UTP T568 A/B Bulk Pack
RVAMJKUTG-S1 (Green TIA)	REVConn 10GX Jack Green TIA UTP T568 A/B Single Pack
RVAMJKUTG-B24 (Green TIA)	REVConn 10GX Jack Green TIA UTP T568 A/B Bulk Pack
RVAMJKUTB-S1 (Blue TIA)	REVConn 10GX Jack Blue TIA UTP T568 A/B Single Pack
RVAMJKUTB-B24 (Blue TIA)	REVConn 10GX Jack Blue TIA UTP T568 A/B Bulk Pack
RVAMJKURD-S1 (Red)	REVConn 10GX Jack Red UTP T568 A/B Single Pack
RVAMJKURD-B24 (Red)	REVConn 10GX Jack Red UTP T568 A/B Bulk Pack
RVAMJKUPR-S1 (Purple)	REVConn 10GX Jack Purple UTP T568 A/B Single Pack
RVAMJKUPR-B24 (Purple)	REVConn 10GX Jack Purple UTP T568 A/B Bulk Pack
RVAMJKUOR-S1 (Orange)	REVConn 10GX Jack Orange UTP T568 A/B Single Pack
RVAMJKUOR-B24 (Orange)	REVConn 10GX Jack Orange UTP T568 A/B Bulk Pack
RVAMJKUIV-S1 (Ivory)	REVConn 10GX Jack Ivory UTP T568 A/B Single Pack
RVAMJKUIV-B24 (Ivory)	REVConn 10GX Jack Ivory UTP T568 A/B Bulk Pack
RVAMJKUGY-S1 (Gray)	REVConn 10GX Jack Gray UTP T568 A/B Single Pack
RVAMJKUGY-B24 (Gray)	REVConn 10GX Jack Gray UTP T568 A/B Bulk Pack
RVAMJKUGN-S1 (Green)	REVConn 10GX Jack Green UTP T568 A/B Single Pack
RVAMJKUGN-B24 (Green)	REVConn 10GX Jack Green UTP T568 A/B Bulk Pack
RVAMJKUEW-S1 (Elec. White)	REVConn 10GX Jack Elec White UTP T568 A/B Single Pack
RVAMJKUEW-B24 (Elec. White)	REVConn 10GX Jack Elec White UTP T568 A/B Bulk Pack
RVAMJKUBR-S1 (Brown)	REVConn 10GX Jack Brown UTP T568 A/B Single Pack
RVAMJKUBR-B24 (Brown)	REVConn 10GX Jack Brown UTP T568 A/B Bulk Pack
RVAMJKUBL-S1 (Blue)	REVConn 10GX Jack Blue UTP T568 A/B Single Pack
RVAMJKUBL-B24 (Blue)	REVConn 10GX Jack Blue UTP T568 A/B Bulk Pack
RVAMJKUBK-S1 (Black)	REVConn 10GX Jack Black UTP T568 A/B Single Pack
RVAMJKUBK-B24 (Black)	REVConn 10GX Jack Black UTP T568 A/B Bulk Pack
RVAMJKUAL-S1 (Almond)	REVConn 10GX Jack Almond UTP T568 A/B Single Pack
RVAMJKUAL-B24 (Almond)	REVConn 10GX Jack Almond UTP T568 A/B Bulk Pack
NUMÉRO DE PIÈCE PART NUMBER	DESCRIPTION

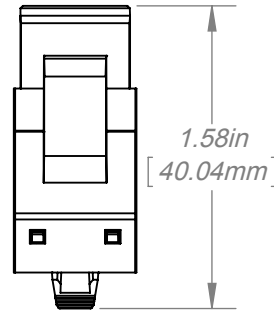

ORIENTATION: 		BELDEN SENDING ALL "THE RIGHT SIGNALS"™	
TITRE / TITLE: REVCONN 10GX JACK			
PROPRIÉTÉ INTELLECTUELLE L'information contenue dans ce document est la propriété de BELDEN Inc. PROPRIETARY INFORMATION The information contained in this document is the property of BELDEN INC.	FORMAT SIZE A	NO DESSIN / DWG. NO. BELDEN-503	REV A
	ÉCHELLE SCALE: 1:1	MASSE WEIGHT: 00.000 LBS	SHEET 1 OF 1