

XFI44U2848-S002 SERVER RACK 44RU/400U x 28w x 48d

- 82.125h x 28w x 48d
- WELDED STEEL FRAME CONSTRUCTION w/ REINFORCED CORNER POSTS
- HEAVY DUTY CASTERS
- HEAVY DUTY LEVELING LEGS
- COLOR: CARDINAL WHITE (C031-WH120) SEMI GLOSS TEXTURE

- (2) PAIR FULLY ADJUSTABLE AND REVERSIBLE EIA/OCF RAILS 44RU / 400U
- RAILS MOUNTED IN EIA CONFIGURATIONS
- SQUARE HOLE TYPE EIA SIDE FOR CAGE NUT
- (50) M6 MOUNTING HARDWARE INCLUDED
- RAIL FINISH IS CLEAR ZINC PLATED
- NUMERICAL MARKINGS FOR EACH RACK UNIT w/ UNIT 1 STARTING @ BOTTOM

- FULL SIZE 78% PERFORATED CONTOUR FRONT & REAR DOOR
- LOCKING SWING HANDLE

CONTOUR PERFORATED DOORS ADD 2.60 INCHES (PER DOOR) TO FRAME DEPTH DIMENSION

- (3)PC TOP PANEL
- FRONT & REAR PANELS HAVE 5-1/4" DIA KNOCKOUTS
- CENTER PANEL IS SOLID
- (4) GROMMETS ON FRONT & REAR PANELS

- PARTIAL BOTTOM PANEL w/ REAR CABLE OPENING

- FLUSH MOUNTED SIDE PANELS w/ TAMPER RESISTANT SCREWS



- (2) 3.5" VERTICAL PDU PANELS MOUNTED IN REAR

- (2) 2.0" VERTICAL LACING PANELS MOUNTED IN REAR

- (2) 6.0" VERTICAL LACING PANELS MOUNTED IN REAR

- BOTTOM FRONT SKIRT

- BOLT TOGETHER KIT w/ STRAP

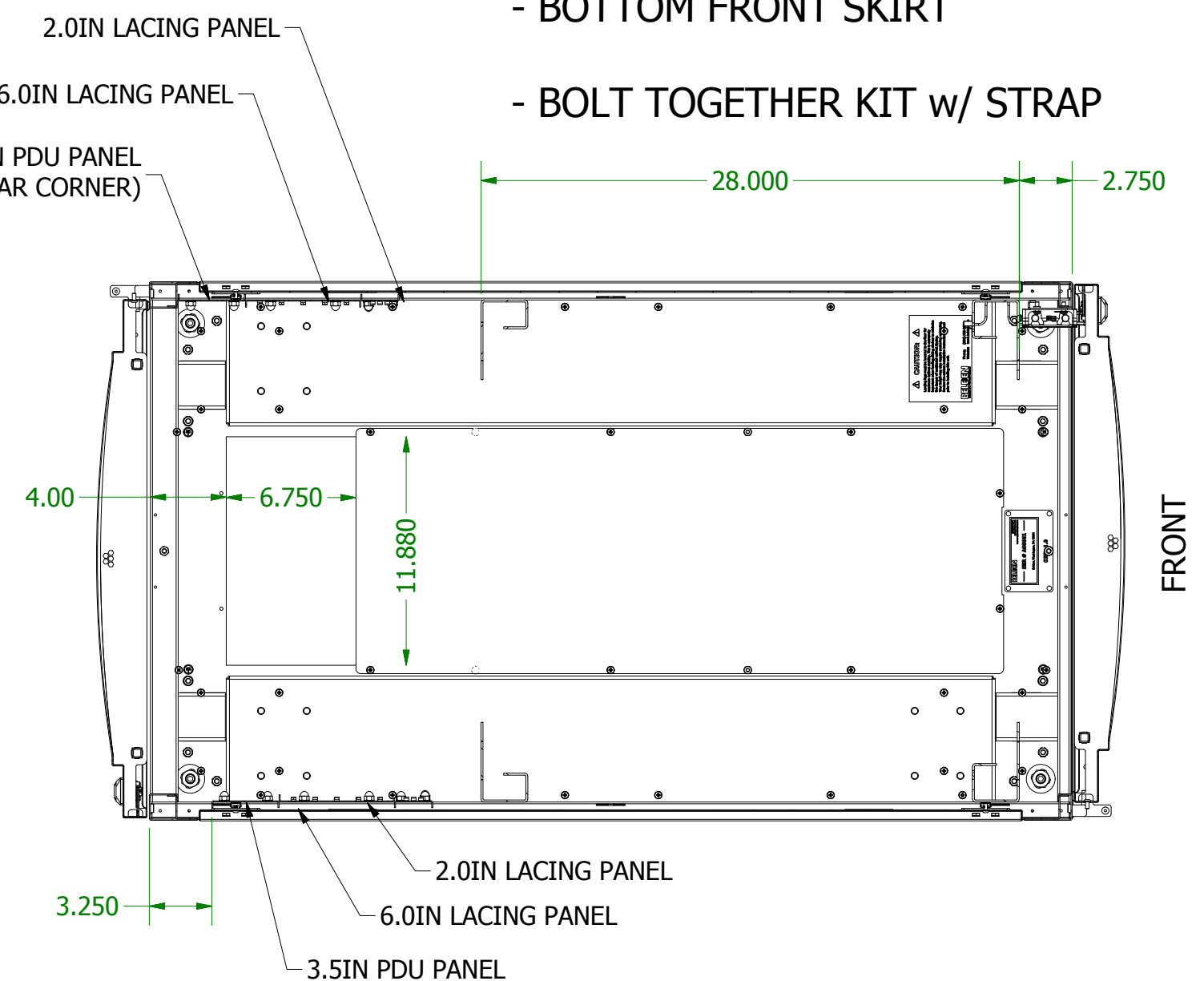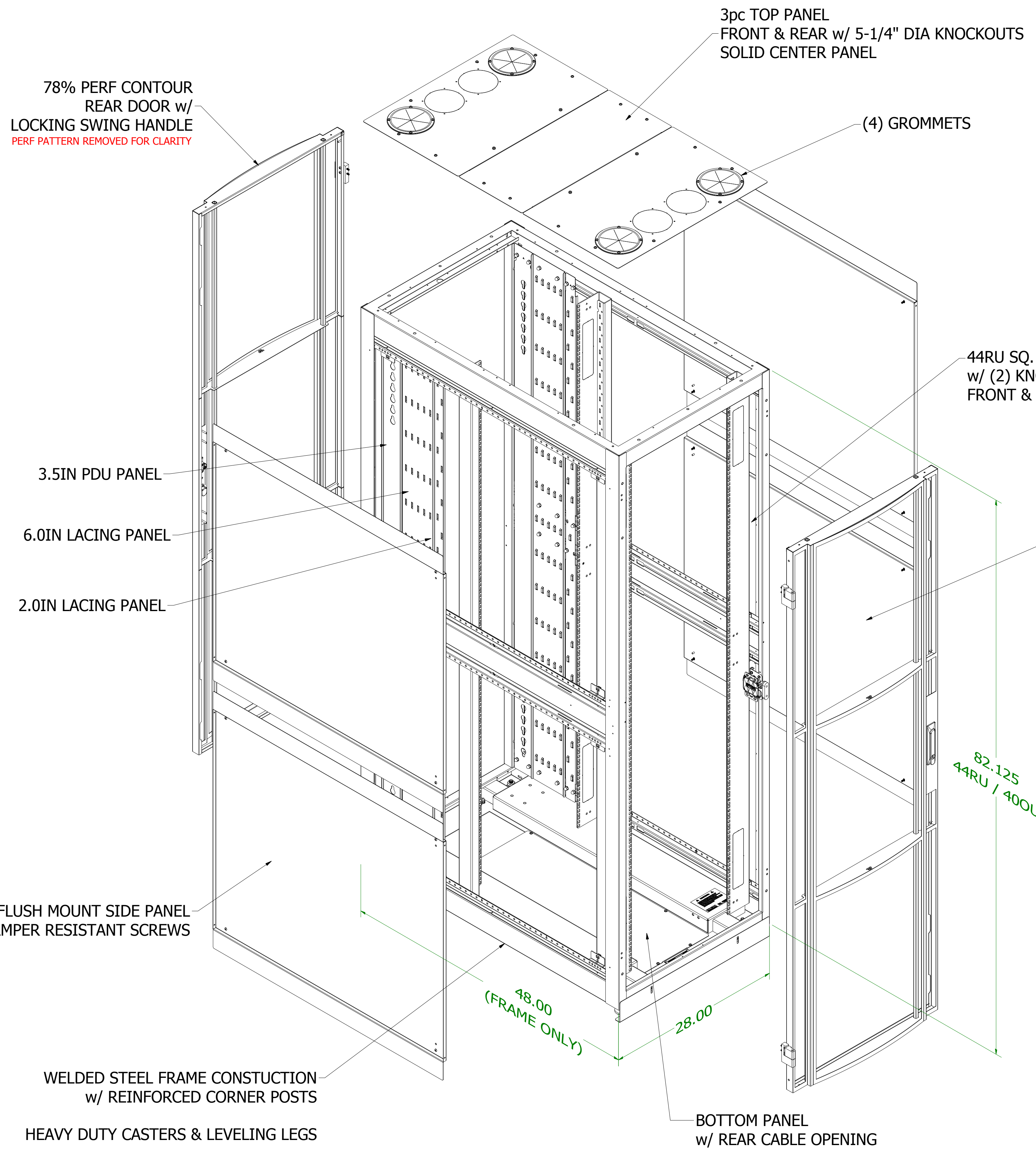

**BELDEN**

THIS DRAWING AND ALL INFORMATION CONTAINED HEREIN IS THE PROPERTY OF BELDEN. ANY USE, COPY OR REPRODUCTION OF THIS MATERIAL WITHOUT WRITTEN PERMISSION OF BELDEN IS PROHIBITED.

XFI44U2848-S002 / SERVER RACK 44RU/400U x 28w x 48d

APPROVED BY: RCG DRAWING AUTHOR: RCG

APPROVAL DATE: 11/15/17

UNITS: INCH Sheet 1 of 1 D

SCALE: 1:8 DATE 11/15/2017

**SUBMITTAL**

REV	DESCRIPTION	BY	DATE