



The **REVConnect 10GX Wall-Mount System** is a very high-density, flexible cross-connect system that meets Category 6A performance when using 10GXS cable terminated with REVConnect Cores as jumpers between user and equipment ports. As the basic component of the system, the REVConnect Coupler (core-to-core connector) is surrounded by cable dressing and patch cable management accessories. When used in a “cut-to-length” fashion (10GXS cable + cores), the REVConnect 10GX Wall-Mount System provides installed cost savings of up to 40% compared to other Category 6A wall-mount cross-connect systems, and reduces operating costs by over 45% by allowing higher termination density and eliminating patch cord slack management.



BENEFITS

- Ease of termination with one method for all components
- Handles the most stringent networking applications
- Maintains tidy cross-connect after moves, adds and changes (MACs)
- Supports large cross-connects in small spaces
- Handles multimedia applications
- Provides migration path to Category 6A for wall-mount cross-connect users



FEATURES

- Uses REVConnect termination technology in user/equipment cables and jumper cables
- Meets and exceeds Category 6A performance, and is backward compatible with Category 6 and Category 5e
- Eliminates patch cord slack with cut-to-length management
- Accommodates any keystone-style component
- Backward compatible with GigaBIX connectors




KEY APPLICATIONS

Data Center

- Entrance Space
- Cross-Connect
- End of Row

Enterprise LAN

- Entrance Space
- Telecommunications Room
- Cross-Connect
- Consolidation Point

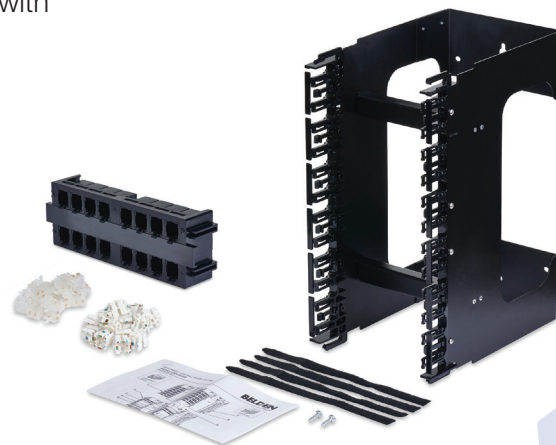

Ordering Information

Description	Belden Part Number
Termination Kits	
REVConnect Wall-Mount Termination Kit Coupler 96-Port (includes 100 cores)	RVAXCTK96CBK
REVConnect Wall-Mount Termination Module Coupler 16-Port (includes 16 cores)	RVAXCTM16CBK
REVConnect Wall-Mount Termination Kit Jack 96-Port (includes 100 cores)	RVAXCTK96JBK
REVConnect Wall-Mount Termination Module Jack 16-Port (includes 16 cores)	RVAXCTM16JBK
Mounts	
REVConnect Wall-Mount Connectivity Mount 96-Port (empty)	RVUXCMT96E
REVConnect Wall-Mount Connectivity Module 16-Port (empty)	RVUXCCM16E
Cable Management Accessories	
REVConnect Wall-Mount Cable Dressing Module	RVUCADM
REVConnect Wall-Mount Patch Cable Management Channel	RVUPCMC
REVConnect Wall-Mount Horizontal Channel Kit	RVUHOCK
REVConnect Couplers	
REVConnect 10GX Coupler Black 568A/B (includes 1 core)	RVACPKUBK-S1
REVConnect 10GX Coupler Black 568A/B Bulk Pack (includes 25 cores)	RVACPKUBK-B24
REVConnect Spare Cores, 50 in pack	RVUCOEW-B50
Cross-Connect Cables	
10GXS Small-Diameter Cables, UTP 4-Pair, 23 AWG, Riser-CMR, Nonbonded-Pair (various colors available)	10GXS12XXXA1000
10GXS Small-Diameter Cables, UTP 4-Pair, 23 AWG, Riser-CMR, Bonded-Pair (various colors available)	10GXS32XXXA1000

Please replace XXX with the respective color code from the chart below.

Colors	
002	Red
003	Orange
004	Yellow
005	Green
D15	Blue
007	Purple
008	Gray
009	White
010	Black

To learn more, call us at
1.800.BELDEN.1
 or visit www.belden.com/products/enterprise/copper/cross-connect